


# UITVOERING B / BAUFORM B / MOUNTING STYLE B

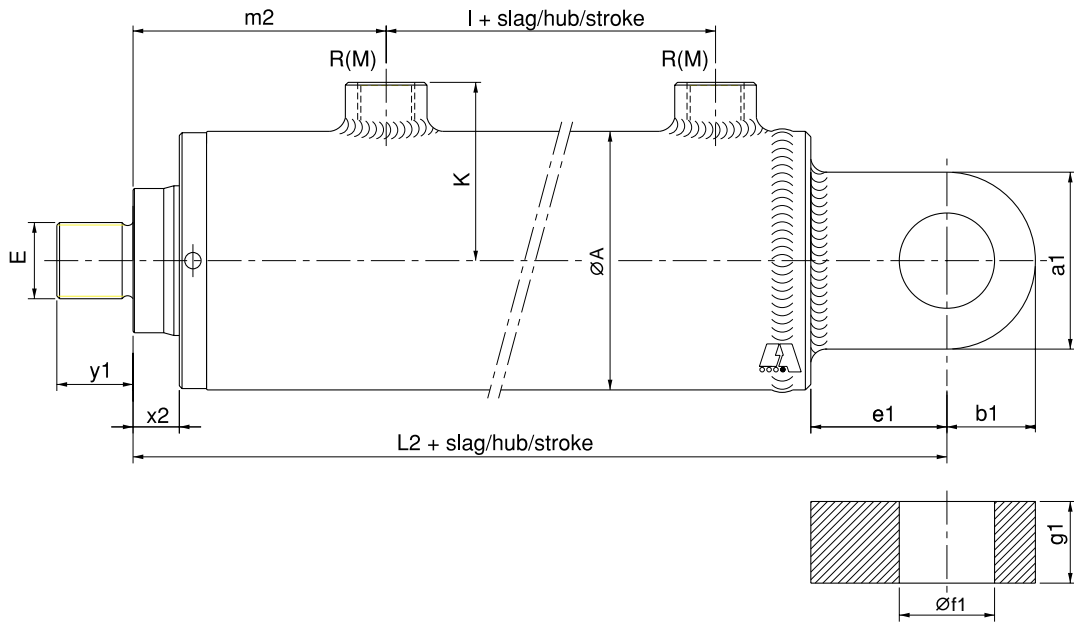

TYPE CILINDER		Afmetingen (mm)													
		R	L2	A	E	K	a1	b1	e1	f1	g1	l	m2	x2	y1
ACDB- 25/	12	R1/8"	118	35	M10 x 1,5	26	35	15	25	12	12	38	40	8	15
ACDB- 25/	16	R1/8"	121	35	M10 x 1,5	26	35	15	25	12	12	25	55	10	15
ACDB- 30/	20 22	R1/4"	158	40	M14X 1,5	36	30	15	25	15	15	53	60	10	14
ACDB- 32/	20 22	R1/4"	158	42	M14X 1,5	37	30	15	25	15	15	53	60	10	14
ACDB- 35/	20 22 25	R1/4"	158	45	M14 x 1,5	39	30	15	25	15	15	53	60	10	14
ACDB- 40/	20 22 25 28 30	R3/8"	176	50	M16 x 1,5	41	35	20	30	20	19	48	67	12	16
ACDB- 50/	25 30 35	R3/8"	200	60	M16 x 1,5	46	45	25	35	25	23	57	75	15	16
ACDB- 60/	30 35 40	R1/2"	219	70	M22 x 1,5	53	55	30	40	30	28	61	82	16	22
ACDB- 63/	32 35 36 40 45	R1/2"	219	75	M22 x 1,5	56	55	30	40	30	28	61	82	16	22
ACDB- 65/	30 32 35 40 45	R1/2"	219	75	M22 x 1,5	56	55	30	40	30	28	61	82	16	22
ACDB- 70/	35 40 45 50	R1/2"	219	80	M22 x 1,5	58	55	30	40	30	28	61	82	16	22
ACDB- 80/	40 45 50 55 60	R1/2"	249	95	M28 x 1,5	66	65	35	50	35	30	68	93	17	28
ACDB- 90/	45 50 55 60 65	R1/2"	249	105	M28 x 1,5	71	65	35	50	35	30	68	93	17	28
ACDB-100/	50 55 60 70	R1/2"	267	115	M35 x 1,5	76	75	40	60	40	35	64	101	17	35
ACDB-110/	50 55 60 70	R1/2"	267	130	M35 x 1,5	84	75	40	60	40	35	64	101	17	35
ACDB-120/	60 70 80 85	R3/4"	320	140	M45 x 1,5	91	95	50	70	50	40	73	128	25	45
ACDB-125/	60 70 80 85 90	R3/4"	320	145	M45 x 1,5	94	95	50	70	50	40	73	128	25	45
ACDB-130/	70 80 85	R3/4"	320	150	M58 x 1,5	96	110	60	70	60	50	73	128	25	58
ACDB-140/	70 80 85 90 100	R3/4"	392	160	M65 x 1,5	101	130	70	75	70	55	108	147	35	65
ACDB-150/	80 85 90 100	R3/4"	392	170	M65 x 1,5	106	130	70	75	70	55	108	147	35	65
ACDB-160/	85 90 100 100	R1"	477	180	M80 x 2	115	146	80	95	80	60	140	177	37	80
ACDB-180/	90 100 110 125 140	R1"	532	210	M100 x 2	130	170	95	110	90	65	150	207	42	100
ACDB-200/	100 110 125 140	R1"	597	230	M110 x 2	139	190	105	120	100	70	170	237	47	110