 




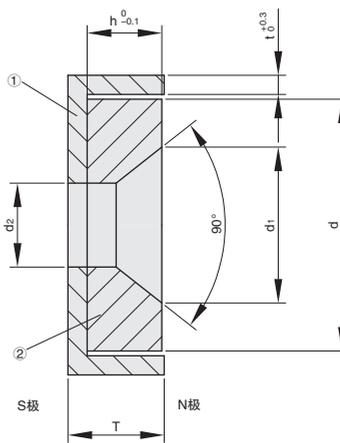

①代号	类型	①		②		最高工作温度
		①材料	①表面处理	②材料	②表面处理	
MTEUYA	方形·带外壳	45#	无电解镀锌	钕磁铁	镀镍	80° C

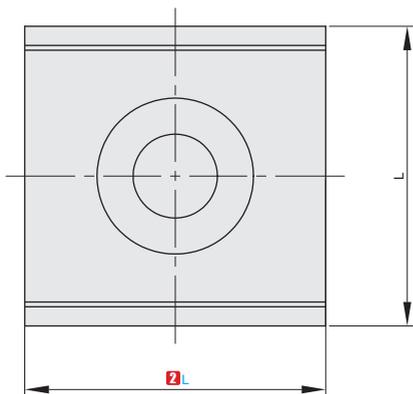

①代号 - ②L  
MTEUYA - L8

K2  
磁铁

①代号	②L	L <sub>1</sub>	P	d	h	d <sub>1</sub>	d <sub>2</sub>	T	t	吸附力 (kgf)	表面磁通密度高斯(G)
MTEUYA	8	15	8	6.5	3.2	5.2	3	4	0.6	0.8	1000~3900
	10	20	10	8	4	6.3	3.5	5	0.8	2	1300~4000
	12	25	12	9.5	4.8	6.3	3.5	6	1	3	3000~4000
	15	30	15	12.5	4.8	9	4.8	6	1	5	3600~4000
	20	40	20	17	5.6	11	5.8	7	1.2	13	3600~4000
	25	50	30	21	6.2	13	7	8	1.6	18.5	3500~4000

▲ 吸附力、表面磁通密度为参考值。

附件：不锈钢平头螺丝 1 个

L	8	10	12	15	20	25
不锈钢平头螺丝	M2.5-8	M3-10	M4-12	M5-15	M6-16	