

不锈钢梅花胀套联轴器





大批量
订购
bulk order

产品特点: 利用胀套连接的梅花弹性体联轴器, 高灵敏度, 传递力矩大,

NEW
新产品



①代号 CPFGZ	主体 [M] 材质 SUS304 不锈钢	弹性体 [M] 材质 进口聚氨酯	表面处理 抛光处理
--------------	-------------------------	---------------------	--------------

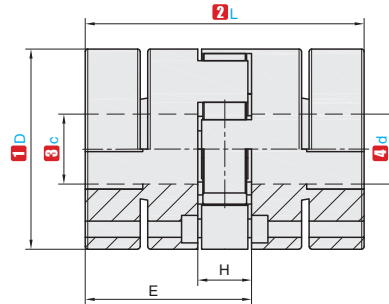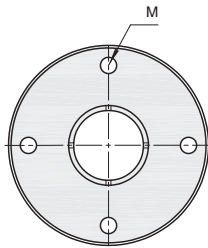

订购编号示例

①代号 - ② D - ③ L - ④ c - ⑤ d
CPFGZ - 55 - 78 - c18 - d20

① 代号	② D	③ L	④ c ⑤ d 可选范围														E	H	M																
CPFGZ	40	66	10	12	12.7	14	15	16	18	19	20	22							39.2	13.7	M4														
	55	78	12		14		15	16	18	19	20	22	24	25	28	30				46.5	16.1	M5													
	65	90							18	19	20	22	24	25	28	30	35					48.05	16.7	M5											
	80	114											19	20	22	24	25	28	30	35	40	45			67.25	22.5	M6								
	95	126													20	22	24	25	28	30	35	40	45	50				73.75	24.0	M8					
	105	140															22	24	25	28	30	35	40	45	50	60			81.8	26.4	M8				
	120	160																			24	25	28	30	35	40	45	50	60	65			91.7	27.4	M10

① 代号	② D	③ L	额定扭矩 (N·m)	容许偏心 (mm)	容许偏角 (°)	容许轴向 偏差 (mm)	容许转速 (rpm)	静态扭转 刚度 (N·m/rad)	惯性矩 (kg·m ²)	重量 (g)
CPFGZ	40	66	19	0.02	1	±0.80	15000	550	1.12×10 ⁻³	280
	55	78	68			±0.80	13000	1510	4.5×10 ⁻³	700
	65	90	190			±0.80	10500	2800	1.9×10 ⁻³	1100
	80	114	270			±0.80	8600	3600	1.9×10 ⁻²	1850
	95	126	440			±1.00	7200	4700	2.2×10 ⁻²	5680
	105	140	720			±1.00	5800	5800	3.3×10 ⁻²	7730
	120	160	1040			±1.00	5200	7200	1.03×10 ⁻¹	9300

▲以上参数由最大孔径测得。