


# 万向球

 
★ 产品特点：转动灵活，耐用，底部螺纹便于安装

## 六角带螺杆型

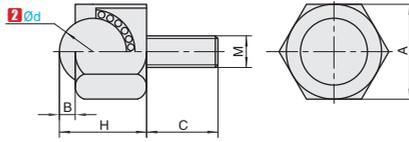

LWSG/LWNG  
六角带螺杆型

①代号	M材质		
	主体	S表面处理	主球
LWSG	40Cr	镀铬	SUJ2
LWNG			POM



视角标准：第一视角




①代号 - ②主球直径d  
LWSG - d38.1

型号		A	B	C	H	M	载重 KG	自重g
①代号	②主球直径d							
LWSG LWNG	12	18	3	12	16	6	30	25
	15.875	24	4	18	22	8	60	80
	25.4	36	6	27	33	12	150	210
	30.16	45	7	30	40	14	250	400
	38.1	55	9	40	50	16	350	700

★ 产品特点：转动灵活，耐用，底部螺纹便于安装

## 直筒螺杆型

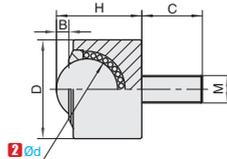

FLSG/FLNG  
直筒螺杆型

①代号	M材质		
	主体	S表面处理	主球
FLSG	40Cr	镀铬	SUJ2
FLNG			POM



视角标准：第一视角




①代号 - ②主球直径d  
FLSG - d25.4

型号		D	B	H	C	M	载重KG	自重g		
①代号	②主球直径d									
FLSG FLNG	12	22	-0.1 -0.2	2.5	17	±0.03	15	8	30	35
	15.875	24		4	21		18	8	60	65
	22.23	36		4.5	31		22	10	150	185
	25.4	38		7.2	31		25	12	180	220
	30.16	44		6.4	36.5		30	16	250	380
	45	62		9	54		45	20	400	1100
	60	96		14	78		50	20	1200	3700


★ 产品特点：转动灵活，耐用，底部螺纹便于安装

## 方形孔固定向下使用型

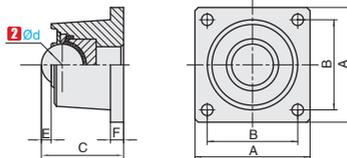

IKSG  
方形孔固定向下使用型

①代号	M材质		
	主体	S表面处理	主球
IKSG	40Cr	镀铬	SUJ2

 

视角标准：第一视角



①代号 - ②主球直径d  
IKSG - d38.1

型号		A	B	C	E	F	G	自重KG	载重g	
①代号	②主球直径d									
IKSG	12	34	26	25	±0.03	3	4.5	4.5	25	70
	19.05	53	41	38		3.5	6	5.5	100	370
	25.4	70	55	50		6	8	7	180	1100
	38.1	100	80	75		9.7	10	9	300	2600
	50.6	130	102	100		13	12	11	600	5300
	76	170	135	125		20	20	18	800	15000