


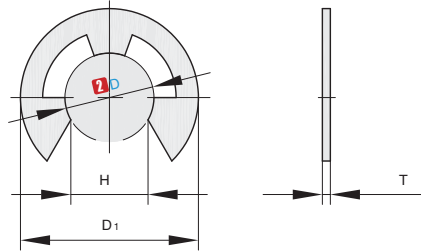


①代号	④材质	⑤硬度	⑥表面处理
RREJB	65Mn	44-53HRC	四氧化三铁保护膜
RREBB	SUS304	37-46HRC	-

▲符合符合GB896



RREJB

 E 型 挡 圈



视角标准：第一视角



①代号 - ②D  
RREJB - D5

订购编号示例

型式	扣环							
①代号	②D	D容差	D1	D1容差	H	H容差	T	T容差
RREJB RREBB	1.2		3	±0.1	1		0.3	±0.025
	1.5		4		1.3		0.4	
	2	0	5		1.7	0	0.4	±0.03
	2.5	-0.09	6		2.1	-0.25	0.4	
	3		7		2.6		0.6	
	4		9		3.5		0.6	
	5	0	11	±0.2	4.3	0	0.6	
	6	-0.12	12		5.2	-0.3	0.8	±0.04
	7		14		6.1		0.8	
	8	0	16		6.9	0	0.8	
9	-0.15	18		7.8	-0.35	0.8		