



ISO straight fitting, female, nickel plated brass.

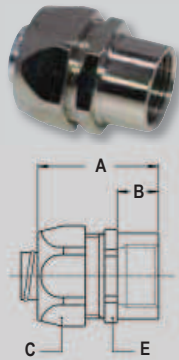

| Thread | Sealtite Size (inch) | Min. Internal Bore (mm) | Dimensions in mm | | | | | Standard Package | Article Number | Weight (Kg/100) |
|-----------|-------------------------|----------------------------|------------------|----|----|---|----|---------------------|-------------------|--------------------|
| | | | A | B | C | D | E | | | |
| M16 x 1,5 | 5/16" | 8,3 | 35 | 12 | 26 | - | 24 | 50 | 812.315.1* | 5,0 |
| M16 x 1,5 | 3/8" | 10,2 | 35 | 12 | 26 | - | 24 | 50 | 812.316.1 | 5,0 |
| M20 x 1,5 | 1/2" | 13,9 | 37 | 13 | 29 | - | 27 | 50 | 812.320.1 | 7,6 |
| M25 x 1,5 | 3/4" | 18,5 | 40 | 15 | 35 | - | 33 | 25 | 812.325.1 | 9,0 |
| M32 x 1,5 | 1" | 23,8 | 46 | 15 | 45 | - | 43 | 10 | 812.332.1 | 18,3 |
| M40 x 1,5 | 1.1/4" | 31,8 | 52 | 16 | 54 | - | 52 | 5 | 812.340.1 | 29,3 |
| M50 x 1,5 | 1.1/2" | 36,8 | 56 | 18 | 63 | - | 60 | 5 | 812.350.1 | 41,2 |
| M63 x 1,5 | 2" | 47,8 | 66 | 20 | 77 | - | 74 | 4 | 812.363.1 | 71,8 |


* Fittings for 5/16" conduit without UL/CSA approval.

ISO straight swivel fitting, male, nickel plated brass, IP 66.

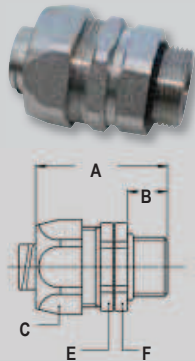

| Thread | Sealtite Size (inch) | Min. Internal Bore (mm) | Dimensions in mm | | | | | Standard Package | Article Number | Weight (Kg/100) |
|-----------|-------------------------|----------------------------|------------------|----|----|----|----|---------------------|-------------------|--------------------|
| | | | A | B | C | E | F | | | |
| M16 x 1,5 | 5/16" | 8,3 | 48 | 10 | 26 | 24 | 21 | 50 | 813.015.1 | 8,1 |
| M16 x 1,5 | 3/8" | 10,4 | 48 | 10 | 26 | 24 | 21 | 50 | 813.016.1 | 8,1 |
| M20 x 1,5 | 1/2" | 13,8 | 49 | 10 | 29 | 27 | 25 | 50 | 813.020.1 | 10,2 |
| M25 x 1,5 | 3/4" | 17,4 | 49 | 10 | 35 | 33 | 31 | 25 | 813.025.1 | 13,8 |
| M32 x 1,5 | 1" | 23,4 | 55 | 12 | 45 | 42 | 38 | 10 | 813.032.1 | 32,5 |
| M40 x 1,5 | 1.1/4" | 29,4 | 58 | 14 | 54 | 50 | 48 | 5 | 813.040.1 | 53,0 |
| M50 x 1,5 | 1.1/2" | 36,9 | 65 | 14 | 62 | 58 | 55 | 5 | 813.050.1 | 74,0 |
| M63 x 1,5 | 2" | 47,9 | 74 | 16 | 76 | 72 | 68 | 4 | 813.063.1 | 130,0 |


ISO 45° fitting, male, nickel plated brass.

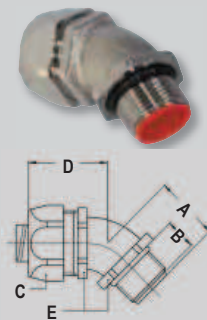

| Thread | Sealtite Size (inch) | Min. Internal Bore (mm) | Dimensions in mm | | | | | Standard Package | Article Number | Weight (Kg/100) |
|-----------|-------------------------|----------------------------|------------------|----|----|----|----|---------------------|-------------------|--------------------|
| | | | A | B | C | D | E | | | |
| M16 x 1,5 | 5/16" | 8,3 | 23 | 12 | 26 | 33 | 22 | 50 | 812.415.1* | 7,3 |
| M20 x 1,5 | 5/16" | 8,3 | 24 | 13 | 26 | 33 | 22 | 50 | 812.414.1* | 7,4 |
| M16 x 1,5 | 3/8" | 10,2 | 23 | 12 | 26 | 33 | 22 | 50 | 812.416.1 | 7,3 |
| M20 x 1,5 | 3/8" | 10,2 | 24 | 13 | 26 | 33 | 22 | 50 | 812.417.1 | 7,4 |
| M20 x 1,5 | 1/2" | 13,9 | 25 | 13 | 29 | 33 | 27 | 50 | 812.420.1 | 10,5 |
| M25 x 1,5 | 3/4" | 18,5 | 30 | 15 | 35 | 36 | 33 | 25 | 812.425.1 | 13,6 |
| M32 x 1,5 | 1" | 23,8 | 34 | 15 | 45 | 46 | 42 | 10 | 812.432.1 | 26,5 |
| M40 x 1,5 | 1.1/4" | 31,8 | 39 | 16 | 54 | 54 | 51 | 5 | 812.440.1 | 44,9 |
| M50 x 1,5 | 1.1/2" | 36,8 | 45 | 18 | 63 | 59 | 60 | 5 | 812.450.1 | 67,5 |
| M63 x 1,5 | 2" | 47,8 | 53 | 20 | 77 | 71 | 74 | 4 | 812.463.1 | 128,0 |

* Fittings for 5/16" conduit without UL/CSA approval.

ISO 90° fitting, male, nickel plated brass.

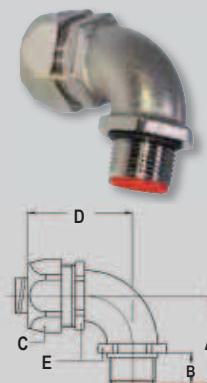

| Thread | Sealtite Size (inch) | Min. Internal Bore (mm) | Dimensions in mm | | | | | Standard Package | Article Number | Weight (Kg/100) |
|-----------|-------------------------|----------------------------|------------------|----|----|----|----|---------------------|-------------------|--------------------|
| | | | A | B | C | D | E | | | |
| M16 x 1,5 | 5/16" | 8,3 | 32 | 12 | 26 | 42 | 22 | 50 | 812.915.1* | 8,2 |
| M20 x 1,5 | 5/16" | 8,3 | 33 | 13 | 26 | 42 | 22 | 50 | 812.914.1* | 8,4 |
| M16 x 1,5 | 3/8" | 10,2 | 32 | 12 | 26 | 42 | 22 | 50 | 812.916.1 | 8,2 |
| M20 x 1,5 | 3/8" | 10,2 | 33 | 13 | 26 | 42 | 22 | 50 | 812.917.1 | 8,4 |
| M20 x 1,5 | 1/2" | 13,9 | 36 | 13 | 29 | 43 | 27 | 50 | 812.920.1 | 12,6 |
| M25 x 1,5 | 3/4" | 18,5 | 43 | 15 | 35 | 48 | 33 | 25 | 812.925.1 | 19,2 |
| M32 x 1,5 | 1" | 23,8 | 48 | 15 | 45 | 59 | 42 | 10 | 812.932.1 | 31,6 |
| M40 x 1,5 | 1.1/4" | 31,8 | 57 | 16 | 54 | 68 | 51 | 5 | 812.940.1 | 56,1 |
| M50 x 1,5 | 1.1/2" | 36,8 | 63 | 18 | 63 | 78 | 60 | 5 | 812.950.1 | 85,3 |
| M63 x 1,5 | 2" | 47,8 | 74 | 20 | 77 | 96 | 74 | 4 | 812.963.1 | 139,8 |

* Fittings for 5/16" conduit without UL/CSA approval.

ANACONDA
FITTINGS

LIQUID-TIGHT
FITTINGS FOR
SEALTITE
IP 67