


# M12 x 1,5


**AZOL GAS**

Accessories


**TNRT**

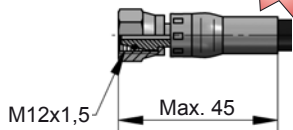

**TNLT**

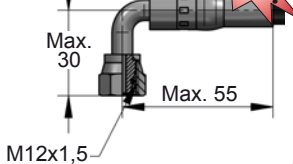

**TNCT**

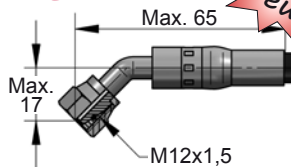

**GF 05**




**Pmax**  
345 bar


**Tmax**  
100 °C

**Rmin**  
40 mm


**RBP 10**

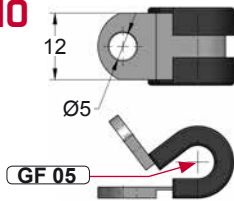


**DRM8**

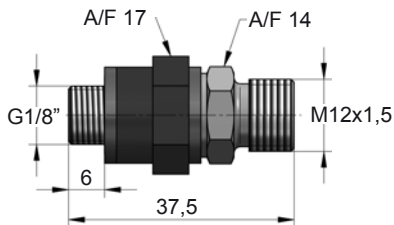


**DRM4**

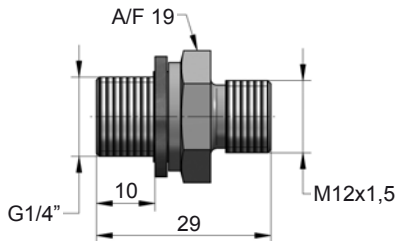


**DLFD**

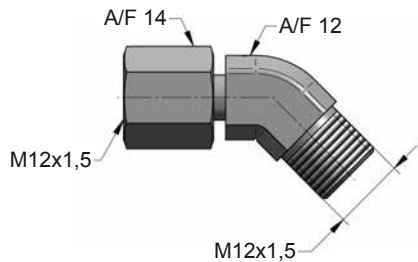


**DCFD**

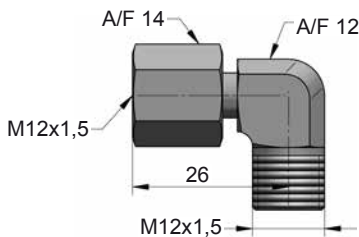


## DWFD

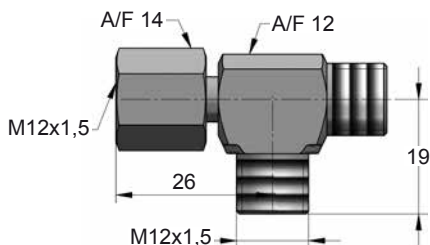


## DTFD

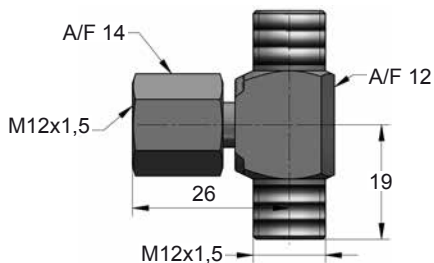


## DIMD

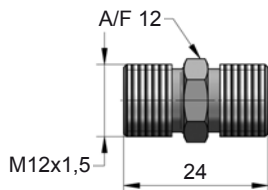

## DCMD

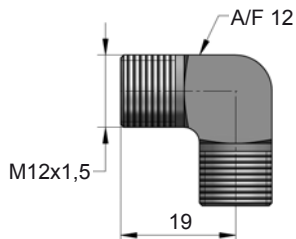

## DTMD

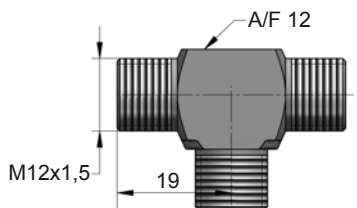

## DXMD

