


Zatrask kulkowy

Ball lock

ZK

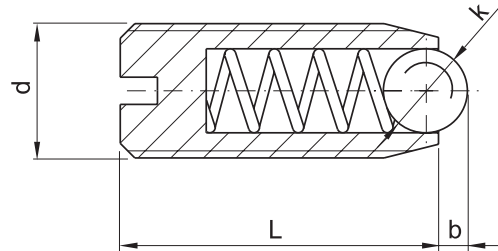


Mat. 1.0503

d	k	L	b	F [N]	NR KAT.
M4	2,5	9	0,8	4 -10	ZK-040
M5	3	12	0,9	6-11	ZK-050
M6	3,5	14	1,0	9-13	ZK-060
M8	5	16	1,5	15-30	ZK-080
M10	6	19	2,0	20-35	ZK-100
M12	8	22	2,5	30-55	ZK-120
M16	10	24	3,5	65-125	ZK-160

Zatrask

Threaded lock

ZR

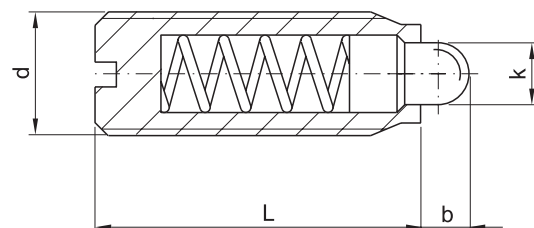

Mat. 1.0503

d	k	L	b	F [N]	NR KAT.
M4	1,8	9	1,5	6-20	ZR-040
M5	2,4	12	2,0	6-20	ZR-050
M6	2,7	14	2,0	7-20	ZR-060
M8	4	16	2,0	15-30	ZR-080
M10	4,5	19	2,5	20-35	ZR-100
M12	6	22	3,5	30-55	ZR-120
M16	8,5	24	4,5	45-100	ZR-160