


Kołek walcowy z gwintem

Dowel pin with thread

KWG

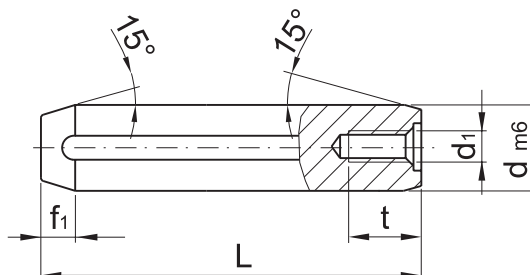

Hartowany
Hardened 60±2 HRC


d	f1	d1	t	L	NR KAT.
6	2,1	M4	6	16	KWG-06016
				18	KWG-06018
				20	KWG-06020
				24	KWG-06024
				28	KWG-06028
				32	KWG-06032
				36	KWG-06036
				40	KWG-06040
				45	KWG-06045
				50	KWG-06050
				55	KWG-06055
				60	KWG-06060
8	2,6	M5	8	20	KWG-08020
				24	KWG-08024
				28	KWG-08028
				32	KWG-08032
				36	KWG-08036
				40	KWG-08040
				45	KWG-08045
				50	KWG-08050
				55	KWG-08055
				60	KWG-08060
				70	KWG-08070
				80	KWG-08080
90	KWG-08090				
100	KWG-08100				
10	3	M6	10	24	KWG-10024
				28	KWG-10028
				32	KWG-10032
				36	KWG-10036
				40	KWG-10040

d	f1	d1	t	L	NR KAT.				
10	3	M6	10	45	KWG-10045				
				50	KWG-10050				
				55	KWG-10055				
				60	KWG-10060				
				70	KWG-10070				
				80	KWG-10080				
				90	KWG-10090				
				100	KWG-10100				
				12	3,8	M6	10	28	KWG-12028
								32	KWG-12032
40	KWG-12040								
45	KWG-12045								
50	KWG-12050								
55	KWG-12055								
60	KWG-12060								
70	KWG-12070								
80	KWG-12080								
90	KWG-12090								
13	3,8	M6	12	100	KWG-12100				
				120	KWG-12120				
				40	KWG-13040				
				50	KWG-13050				
				60	KWG-13060				
				70	KWG-13070				
				80	KWG-13080				
				100	KWG-13100				
				14	4	M8	12	32	KWG-14032
								36	KWG-14036
40	KWG-14040								
45	KWG-14045								
50	KWG-14050								
55	KWG-14055								
60	KWG-14060								

Kołek walcowy z gwintem

Dowel pin with thread

KWG

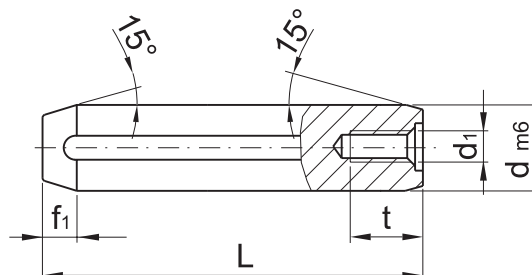

Hartowany
Hardened 60±2 HRC

d	f1	d1	t	L	NR KAT.
14	4	M8	12	70	KWG-14070
				80	KWG-14080
				90	KWG-14090
				100	KWG-14100
				120	KWG-14120
16	4,7	M8	12	32	KWG-16032
				36	KWG-16036
				40	KWG-16040
				45	KWG-16045
				50	KWG-16050
				55	KWG-16055
				60	KWG-16060
				70	KWG-16070
				80	KWG-16080
				90	KWG-16090
100	KWG-16100				
120	KWG-16120				

d	f1	d1	t	L	NR KAT.
20	6	M10	16	36	KWG-20036
				40	KWG-20040
				45	KWG-20045
				50	KWG-20050
				55	KWG-20055
				60	KWG-20060
				70	KWG-20070
				80	KWG-20080
				90	KWG-20090
				100	KWG-20100
25	6	M16	24	120	KWG-20120
				50	KWG-25050
				60	KWG-25060
				70	KWG-25070
				80	KWG-25080
				90	KWG-25090
				100	KWG-25100
				120	KWG-25120