
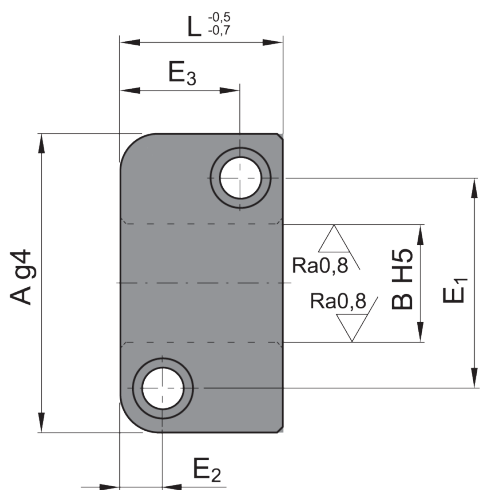
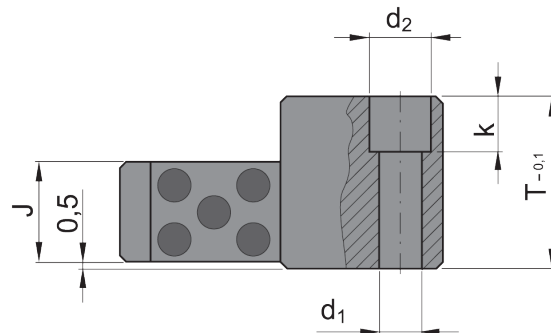



Zamek boczny

Side lock

MS51

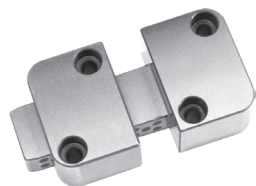

Część „A”
Part "A"

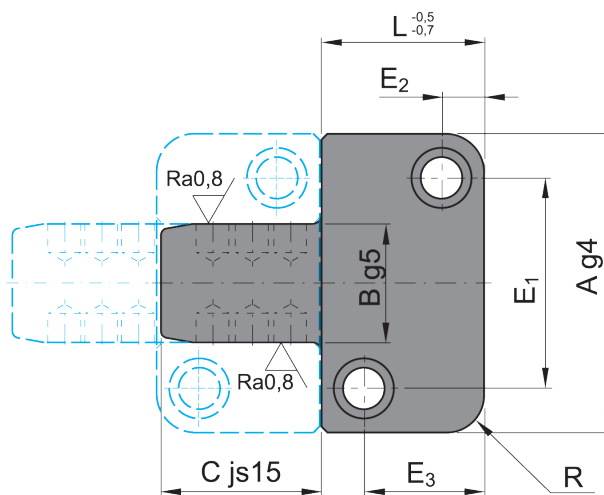

Część „B”
Part "B"

Twardość / hardness
„A” 58-60 HRC
„B” 54-56 HRC

L	C	A	T	B	J	E1	E2	E3	R	d1	d2	k	NR KAT.
22	20	40	20	16	11	26	7	15	6	6,6	11	6,8	MS51-22020
	40												MS51-22040
27	25	45	22	20	13	31	7	19	6	6,6	11	6,8	MS51-27025
	50												MS51-27050
36	32	50	25	25	14	35	9	27	8	6,6	11	6,8	MS51-36032
	63												MS51-36063
46	40	63	32	32	19	45	11	35	8	9	15	9	MS51-46040
	80												MS51-46080
56	50	85	36	40	22	60	15	40	10	11	18	11	MS51-56050
	100												MS51-56100
66	56	100	40	50	24	74	18	48	10	14	20	13	MS51-66056
	112												MS51-66112