


KMA pivoting | Recommended for unsupported and gliding applications
KMA locking | Recommended for vertical hanging and standing applications

Width index	Part No. full set KMA pivoting	Part No. full set KMA locking	Bi [mm]	Width index	Part No. full set KMA pivoting	Part No. full set KMA locking	Bi [mm]
05.	E4.640. 05 .12.C*	E4.641. 05 .12.C*	050	23.	E4.640. 23 .12.C*	E4.641. 23 .12.C*	237
06.	E4.640. 06 .12.C*	E4.641. 06 .12.C*	062	25.	E4.640. 25 .12.C*	E4.641. 25 .12.C*	250
07.	E4.640. 07 .12.C*	E4.641. 07 .12.C*	075	26.	E4.640. 26 .12.C*	E4.641. 26 .12.C*	262
08.	E4.640. 08 .12.C	E4.641. 08 .12.C	087	27.	E4.640. 27 .12.C*	E4.641. 27 .12.C*	275
10.	E4.640. 10 .12.C*	E4.641. 10 .12.C*	100	28.	E4.640. 28 .12.C*	E4.641. 28 .12.C*	287
11.	E4.640. 11 .12.C*	E4.641. 11 .12.C*	112	30.	E4.640. 30 .12.C*	E4.641. 30 .12.C*	300
12.	E4.640. 12 .12.C*	E4.641. 12 .12.C*	125	31.	E4.640. 31 .12.C*	E4.641. 31 .12.C*	312
13.	E4.640. 13 .12.C*	E4.641. 13 .12.C*	137	32.	E4.640. 32 .12.C*	E4.641. 32 .12.C*	325
15.	E4.640. 15 .12.C	E4.641. 15 .12.C	150	33.	E4.640. 33 .12.C*	E4.641. 33 .12.C*	337
16.	E4.640. 16 .12.C*	E4.641. 16 .12.C*	162	35.	E4.640. 35 .12.C*	E4.641. 35 .12.C*	350
17.	E4.640. 17 .12.C*	E4.641. 17 .12.C*	175	36.	E4.640. 36 .12.C*	E4.641. 36 .12.C*	362
18.	E4.640. 18 .12.C*	E4.641. 18 .12.C*	187	37.	E4.640. 37 .12.C*	E4.641. 37 .12.C*	375
20.	E4.640. 20 .12.C*	E4.641. 20 .12.C*	200	38.	E4.640. 38 .12.C*	E4.641. 38 .12.C*	387
21.	E4.640. 21 .12.C*	E4.641. 21 .12.C*	212	40.	E4.640. 40 .12.C*	E4.641. 40 .12.C*	400
22.	E4.640. 22 .12.C*	E4.641. 22 .12.C*	225				

(KMA = polymer metal mounting bracket) For the C-profile option please add index **C**. Width available upon request. Please consult igus® for delivery time.

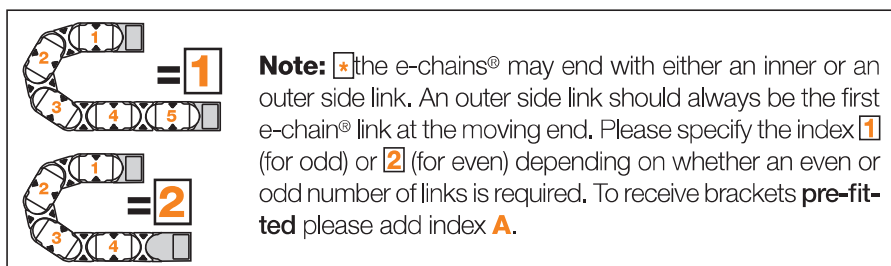

E4.640.150.2.12.C A Order example

- A** ... To indicate option with brackets pre-fitted
- C**-profile option
- Full set
- Even numbers of links
- Width index
- e-chain® series

Strain relief e.g. clamps, tiwrap plates, nuggets and plug-in clips are available from stock. The complete chainfix range with ordering options ► From page 1098