


TopTherm wall-mounted cooling units "Blue e", NEMA 4X

Output class 2000 – 2500 W

Model No.	Packs of	3328.504	3328.544	3329.504	3329.544	Page
Material	Stainless steel	■	■	■	■	
Total cooling output 50 Hz L35 L35 to DIN EN 14511 kW		2.2	2.2	2.55	2.55	
Total cooling output 50/60 Hz L35 L35 kW		2.2 / 2.36	2.2 / 2.35	2.55 / 2.66	2.55 / 2.7	
Total cooling output 50/60 Hz L35 L50 kW		1.62 / 1.75	1.45 / 1.69	1.84 / 1.92	1.9 / 1.95	
Rated operating voltage V, ~, Hz		230, 1~, 50/60	400, 3~, 50 460, 3~, 60	230, 1~, 50/60	400, 3~, 50 460, 3~, 60	
Width mm		405	405	405	405	
Height mm		1650	1650	1650	1650	
Depth mm		388	388	388	388	
Rated current max. A		6.1 / 6.6	2.8 / 3.3	8.2 / 9.3	3.7 / 3.8	
Start-up current A		20 / 22	6.8 / 7.8	20 / 24	6.8 / 7.6	
Pre-fuse A		16	–	16	–	
Motor circuit-breaker A		–	6.3...10	–	6.3...10	
Power consumption P _{el} 50/60 Hz L35 L35 kW		0.92 / 1.06	0.92 / 1.15	1.21 / 1.35	1.2 / 1.4	
Power consumption P _{el} 50/60 Hz L35 L50 kW		1.06 / 1.25	1.15 / 1.4	1.41 / 1.64	1.44 / 1.75	
Operating temperature range		+10°C...+50°C	+10°C...+50°C	+10°C...+50°C	+10°C...+50°C	
Setting range		+20°C...+50°C	+20°C...+50°C	+20°C...+50°C	+20°C...+50°C	
Energy efficiency ratio (EER) 50 Hz L35 L35 to DIN EN 14511		2.4	2.4	2.11	2.11	
Refrigerant g		R134a, 900	R134a, 900	R134a, 900	R134a, 900	
Permissible operating pressure (p. max.) bar		28	28	28	28	
Air throughput of fans (unimpeded air flow), Internal circuit / external circuit m ³ /h		980 / 980	900 / 900	1230 / 1230	1200 / 1200	
Weight kg		80.0	81.0	83.0	84.0	
Accessories						
Door-operated switch	1 pc(s).	4127.010	4127.010	4127.010	4127.010	639

Accessories

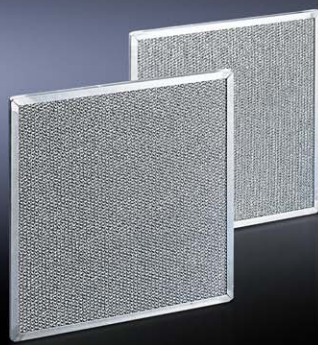

Metal filters

see page 370