


SERIES 82AF



PUNCTURE-PROOF PNEUMATIC WHEELS WITH POLYPROPYLENE CENTRE SWIVEL TOP PLATE TYPE NL

Wheel description

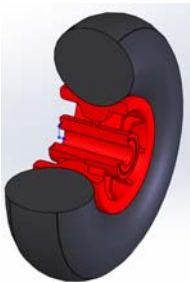


Tread: in expanded polyurethane.

Centre: in red polyurethane.

Hub: with cylindrical roller bearing with plastic cage.

Bracket description

Light duty bracket type NL (max carrying capacity 70 daN)

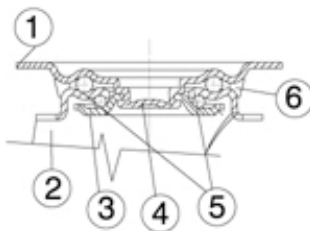

1) **Plate:** electrolytically galvanised steel plate

2) **Fork:** electrolytically galvanised steel plate

3) **Ball Racing Ring:** electrolytically galvanised steel plate

4) **King Pin:** incorporated in top plate and cold riveted

5) **Swivel actions:** double ring of greased balls

6) **Dust seal:** orange polyethylene

Finishing: electrolytic galvanisation

Fitting: top plate