


ZAKO ring with O-ring ZAKO system Low Pressure

O-ring is supplied
seperately

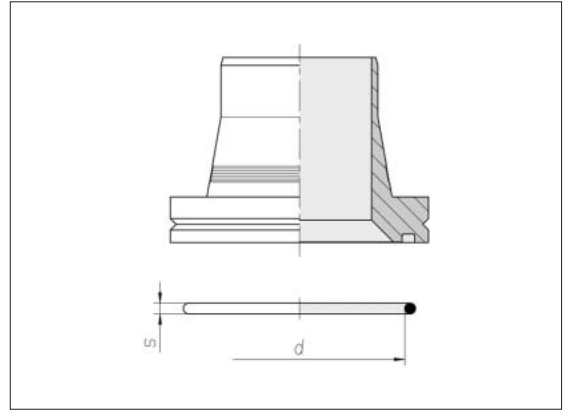

Flange size NW	Tube d x s	O-ring d x s	Order No.
1 1/2"	48.3 x 3.2	47.22 x 3.53	0 5 17 10 20 67
1 1/2"	48.3 x 4	47.22 x 3.53	0 5 17 00 20 67
2"	60.3 x 3.6	56.74 x 3.53	0 5 17 20 20 67
2 1/2"	60.3 x 3.6	69.44 x 3.53	0 5 17 12 20 67
2 1/2"	60.3 x 4.5	69.44 x 3.53	0 5 17 02 20 67
3"	76.1 x 3.6	85.32 x 3.53	0 5 17 14 20 67
3"	76.1 x 4.5	85.32 x 3.53	0 5 17 04 20 67
3 1/2"	88.9 x 3.6	98.02 x 3.53	0 5 17 16 20 67
3 1/2"	88.9 x 5	98.02 x 3.53	0 5 17 06 20 67
5"	114.3 x 3.6	136.12 x 3.53	0 5 17 18 20 67
5"	114.3 x 6.3	136.12 x 3.53	0 5 17 08 20 67