


Union tees

Tube coupling: VOSS Lok 40

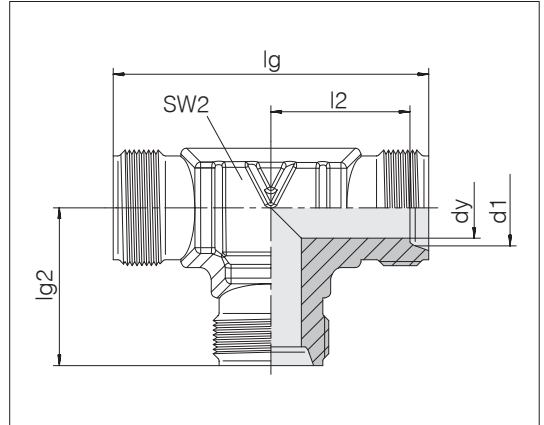

Tube OD d_1	d_y	lg	lg_2	l_2	SW2	kg/100 ca.	Order-No.	Designation
6	4.5	41.6	20.8	18.2	12	3.6	7000909800	40-T-6-SST
8	6.5	43.6	21.8	19.1	14	4.5	7000910700	40-T-8-SST
10	8	47.6	23.8	20.8	17	7.6	7000910900	40-T-10-SST
12	9.5	54.6	27.3	24.2	19	11.3	7000911100	40-T-12-SST
14	11.5	60.6	30.3	27.1	22	17.4	7000911300	40-T-14-SST
15	12	60.6	30.3	27	22	16.7	7000911500	40-T-15-SST
16	13	60.6	30.3	26.8	22	15.3	7000911700	40-T-16-SST
18	15	65.2	32.6	29	27	24.5	7000911900	40-T-18-SST
20	16	68	34	30.3	30	32.9	7000912100	40-T-20-SST
22	18	68	34	30	30	28.8	7000912300	40-T-22-SST